




HELUKABEL®

Using PROFINET® cables? Make
sure they are CONNECTORIZED!

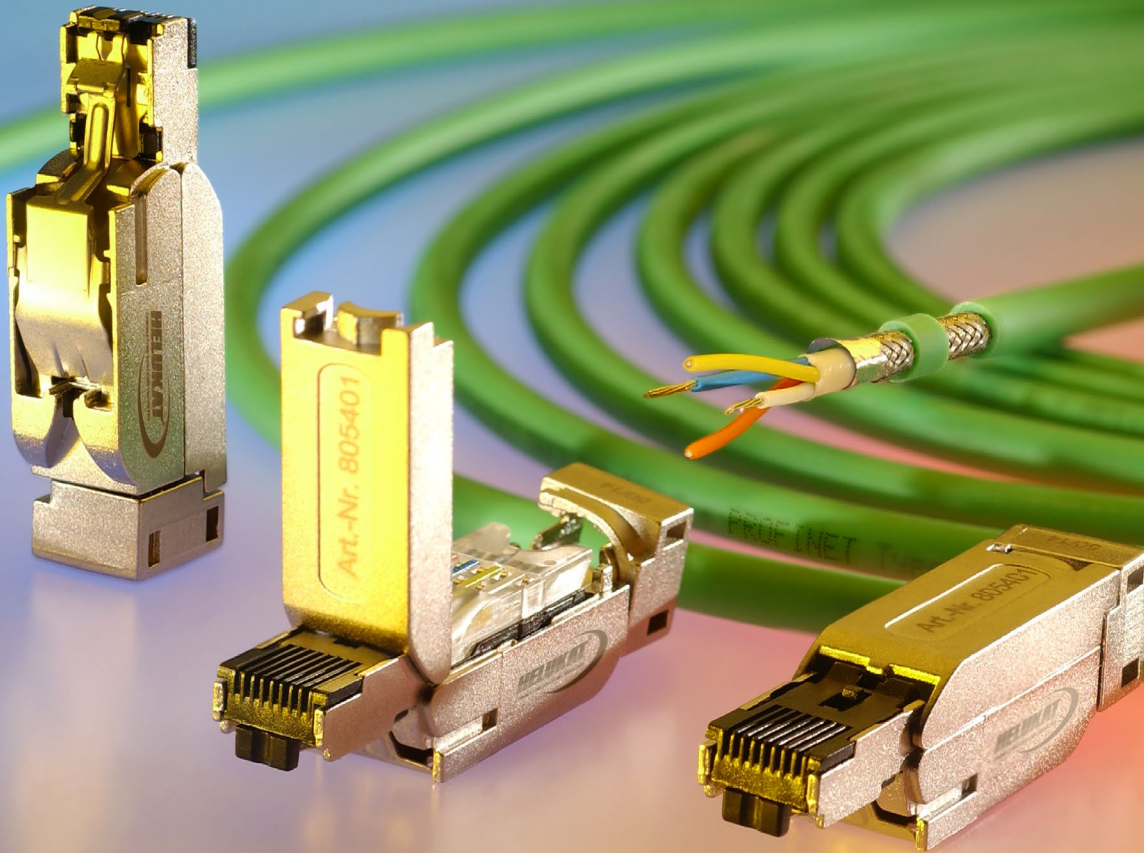

RJ45 CONNECTORS

Industrial Ethernet

PROFINET® Connectors


Industrial RJ45 plugs



IP 20 Connectors



HELUKABEL®

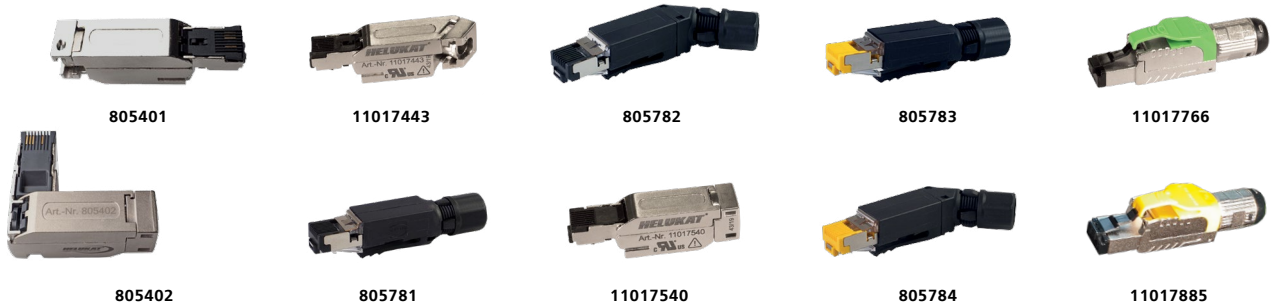

Part No.	Category	Connector type	Housing	Cable-Ø	AWG Dr.	AWG Li.	Temperature range	Pins	Standard
805401	Cat 5	Straight 180°	Metal	6,3 - 6.7 mm	22-24		-20°C - 70°C	4	PROFINet
805402		*Angled 90°	Metal				-20°C - 70°C	4	PROFINet
11017443		*Angled 145°	Metal				-20°C - 70°C	4	PROFINet
805781		Straight 180°	Plastic	4,5 - 9,0 mm	22-24	22-27	-40°C - 70°C	4	PROFINet
805782		*Angled 45°	Plastic	4,5 - 8,0 mm			-40°C - 70°C	4	PROFINet
11017540	Cat 6	Straight 180°	Metal	7,6 - 8,0 mm	24	24/7	-20°C - 70°C	8	PROFINet
805783	Cat 6E _A	Straight 180°	Plastic	4,5 - 9,0 mm	22-24	22-27	-40°C - 70°C	8	TIA 568 A/B
805784	Cat 6E _A	*Angled 45°	Plastic	4,5 - 8,0 mm	22-24	22-27	-40°C - 70°C	8	TIA 568 A/B
11017766	Cat 6 _A	Straight 180°	Metal	7,0 - 8,5 mm	26-23	26-23	-40°C - 70°C	8	TIA 568 A/B
11017885	Cat 6 _A	Straight 180°	Metal	6,0 - 7,5 mm	26-23	26-23	-40°C - 70°C	8	TIA 568 A/B

* Connector outlet is flexible in 4 directions.

For more information on these and other PROFINET® industrial RJ45 plug connectors, or M12 field wireable connectors, please contact your local HELUKABEL branch.

Process PROFINET® cables in the field... with ease!

Application

Dismantling and stripping of PROFINET® Type A, B and C cables

Details

- Three-stage stripping of jacket, shield and filler
- Knife cartridges can be inserted on either side
- Standard port for PROFINET® cables with 6.5 mm outer diameters
- Tool has versatile uses thanks to adjustable screw holders, replacement knife cartridges or other cable types, e.g. coaxial cables

Options

Knife cartridges for other cable types or constructions



PROFINET®
Cable Stripper Part No. 801497

helukabel.com