


HELUTOOL HAM 29

Universal outer sheath cutter with spring quick clamping system

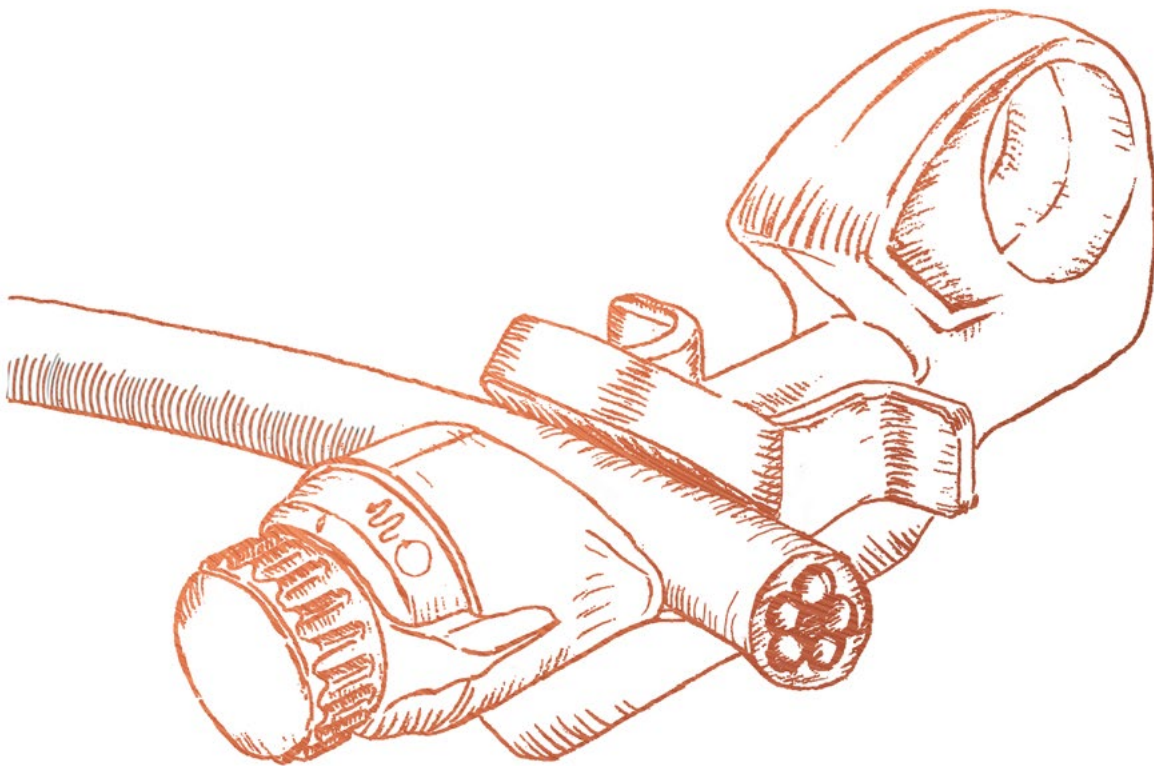

UNIVERSAL OUTER SHEATH CUTTER WITH SPRING QUICK CLAMPING SYSTEM

Precise:

Cutting depth adjustable up to 3 mm – underlying cable layers are not damaged

Versatile:

Easily adjusted for round, spiral and longitudinal cuts

Safe:

Innovative design minimises risk of injury

Efficient:

Blade suitable for almost all cable insulation

Simple:

No jamming due to axial pulling of the tool in longitudinal direction

Durable:

Blocking system prevents opening in the „longitudinal cut“ position and thus protects the blade from damage in the event of incorrect use

Ergonomic:

Optimally adapted shape enables fatigue-free work


Technical Characteristics:

- Wide range of applications: diameters from 4.5 to 29 mm
- Suitable for soft and hard cable insulation
- Hardened steel blade
- Specially ground blade for clean removal of the outer sheath
- Round, spiral and longitudinal cuts possible
- No tilting due to axial pulling of the device in the longitudinal direction
- Cutting depths adjustable up to 3 mm in increments of 0.1 mm
- Cable layers underneath are not damaged
- Working without resistance due to gliding support surface
- Compact design
- Handy and ergonomic design
- Blocking system prevents opening in the „rip cut“ position and thus protects the blade from damage if used incorrectly
- Switch the adjusting ring to the „Longitudinal cut“ symbol and device axially in pull lengthwise

Instruction Manual:


Scan QR code for instructions
helukabel.com/ham29

Order via shop:


Scan QR code to order
shop.helukabel.com

Tool	Part no.	Quantity [Pieces]
HELUTOOL HAM 29 – Universal outer sheath cutter with spring quick clamping system	11022249	1